




Inch | Metric

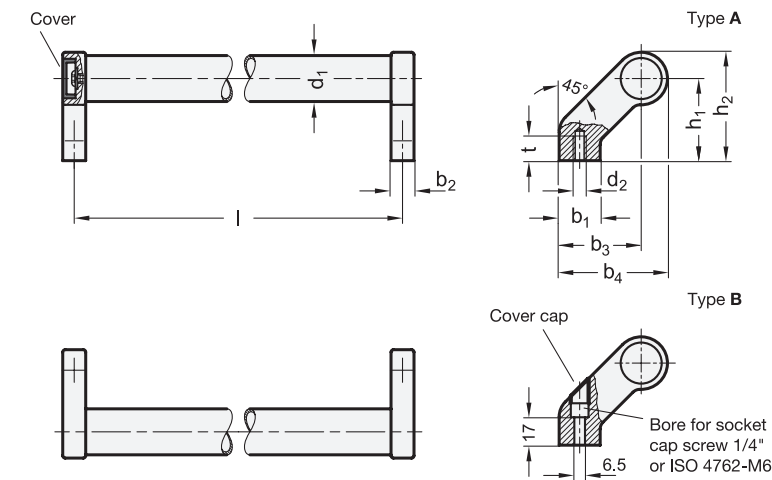

Type

- A Mounting from the back (tapped blind hole)
B Mounting from the operator's side (only for d₁ = 28 mm)

Inch table

1								2							
d ₁	Length l ±0.01							d ₂	b ₁	b ₂	b ₃	b ₄	h ₁	h ₂	t min.
0.79 20.1	7.00 177.8	8.00 203.2	10.00 254	12.00 304.8	16.00 406.4	-	-	1/4 x 20	0.94 23.9	0.47 11.9	1.65 41.9	2.13 54.1	1.65 41.9	2.13 54.1	0.47 11.9
1.10 27.9	8.00 203.2	10.00 254	12.00 304.8	16.00 406.4	20.00 508	24.00 609.6	-	5/16 x 18	0.98 24.9	0.55 14	1.97 50	2.60 66	1.97 50	2.60 66	0.59 15

Dimensions in: inches / millimeters

Metric table

1								2							
d ₁	Length l ±0.25							d ₂	b ₁	b ₂	b ₃	b ₄	h ₁	h ₂	t min.
20 0.79	180 7.09	200 7.87	250 9.84	300 11.81	350 13.78	400 15.75	-	M 6	24 0.94	12 0.47	42 1.65	54 2.13	42 1.65	54 2.13	12 0.47
28 1.10	200 7.87	250 9.84	300 11.81	350 13.78	400 15.75	500 19.69	600 23.62	M 8	25 0.98	14 0.55	50 1.97	66 2.60	50 1.97	66 2.60	15 0.59
30 1.18	200 7.87	300 11.81	350 13.78	400 15.75	500 19.69	600 23.62	1000 39.37	M 8	27 1.06	17 0.67	51 2.01	68 2.68	51 2.01	68 2.68	15 0.59

Dimensions in: millimeters / inches

Specification

Handle tube

- Aluminum, wall thickness 1.5 mm
- Powder coated
 - Black, RAL 9005, textured finish
- Anodized finish, natural color
 - Handle legs black
- Anodized finish, natural color
 - Handle legs silver

- SW
- EL
- ES

Handle legs

- Zinc die-cast
- Powder coated, textured finish
 - Black, RAL 9005 (for SW / EL)
 - Silver, RAL 9006 (for ES)

Covers

- Plastic, light gray

Cover cap (Type B)

- Plastic
 - Black (for SW / EL)
 - Light gray (for ES)

RoHS

The handle tube of the tubular handles GN 333 can be screwed to the handle bases without further machining or processing, allowing special lengths to be realised easily.

A typical application area for tubular handles GN 333 are double-winged doors at machines or devices.

Further handle legs can be added for very long tubular handles. Individual handle legs for tubular handles Ø 28 (type A) are available under GN 333.8.

Technical Information

Load Capacity Information

QVX

Accessory

GN 333.8 Angled Handle Legs (for Tubular Handles Ø 28 mm)

QVX

How to order (Inch)

GN333-0.79-7.00-A-EL

- 1 Handle diameter d₁
- 2 Length l
- 3 Type
- 4 Finish

How to order (Metric)

GN333-20-180-A-EL

- 1 Handle diameter d₁
- 2 Length l
- 3 Type
- 4 Finish