



**Assembly instructions**

The minimum thickness for the profile suitable for use is 15 mm, while the distance between door and frame must be within 2.5 mm and 3.5 mm.

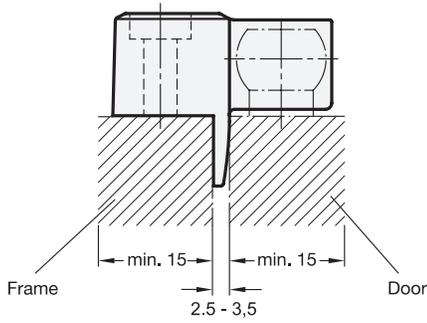


For applications with differences in height between frame and door, EN 450.1 spacer with height  $h = 5 \text{ mm}, 10 \text{ mm}$  and  $15 \text{ mm}$  are available.

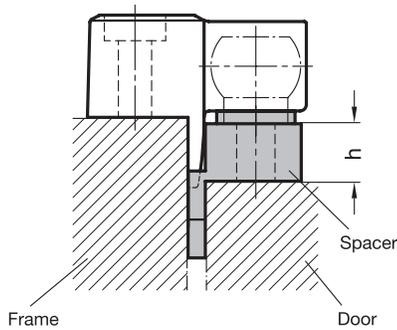

**EN 450.1 Spacers**

Technopolymer Plastic, for EN 450 Ball Shaped Door Catches

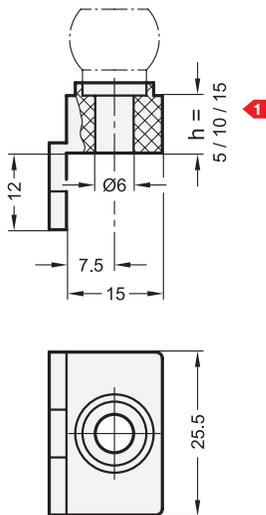

ELESA original design BPS.30-SP

**Specification**

- Plastic  
Technopolymer (Polyamide PA)  
Black, matte finish

**Information**

In addition to the basic spacing distances of 5 mm, 10 mm and 15 mm, combinations of spacers can provide distances of 20 mm, 25 mm and 30 mm as well.

<p>How to order</p> <p><b>EN 450.1-10</b></p>	<p>1 Height h</p>
---	-------------------